 



# Tabbed Brackets - For 1 Slot

## For 8 Series (Slot Width 10mm) Aluminum Extrusions



■ **Features:** Tabbed Brackets to be connected by both L and Cross-Connections.


### ■ Tabbed Reversal Brackets

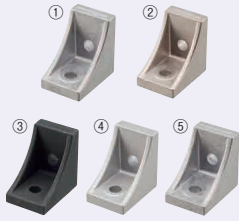

Type	Material	Surface Treatment
① HBLFSNF8	-	-
② HBLFSN8	-	-
③ HBLFSNB8	ADC12	Black Anodize
④ HBLFSNM8		Electroless Nickel Plating
⑤ CHBLFSN8		Baked Paint (Silver)

\* Baked Paint (Silver) is color coordinated with Clear Coating Extrusions.



### ■ Tabbed Reversal Brackets (Depth 40mm)

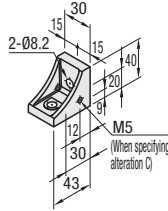

### ■ Tabbed Reversal Brackets

HBLFSN8  
HBLFSNB8 (Black Anodize)

HBLFSNM8 (Electroless Nickel Plating)  
CHBLFSN8 (Baked Paint, Silver)

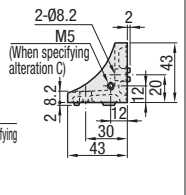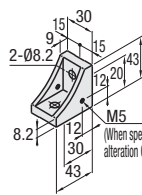


Part Number	Mass (g)	Applicable Screw, T Nut		Allowable Load (N)	Unit Price (1-99 pc(s))	Volume Discount Rate (100~200)
		Screw	T Nut			
HBLFSNF8	48					
HBLFSN8						
HBLFSNB8* (Black Anodize)	50	CBM8-20	2 HNTT8-8	2 2058		
HBLFSNM8 (Electroless Nickel Plating)						
CHBLFSN8 (Baked Paint, Silver)						

\* For repairing black anodizing, refer to P.846.



Example

Can be installed in either direction.

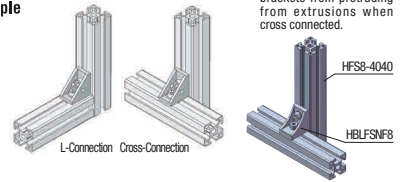


■ HBLFSN8 prevents brackets from protruding from extrusions when cross connected.

HFS8-4040



HBLFSN8

■ **Features:** Brackets with tabs to fit in slots of extrusions and stop rotating when tightening.

### ■ Tabbed Brackets

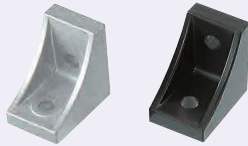

HBLFS8  
HBLFSB8  
(Cathodic Electrodeposition Paint: Black)

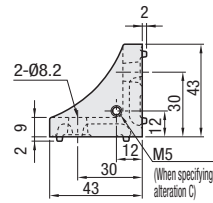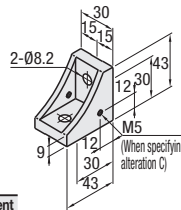

Type	Material	Surface Treatment
HBLFS8	-	-
HBLFSB8	ADC12	Cathodic Electrodeposition Coating: Black

Part Number	Mass (g)	Applicable Screw, T Nut		Allowable Load (N)	Unit Price (1-99 pc(s))	Volume Discount Rate (100~200)
		Screw	T Nut			
HBLFS8	54	CBM8-20	2 HNTT8-8	2 2058		
HBLFSB8* (Cathodic Electrodeposition Paint: Black)						



Example

Used for L connection.





■ **Features:** One-Sided Tabbed Rib Brackets. Easy to work with wrenches.

### ■ One-Side Rib Brackets




HBLFSL8

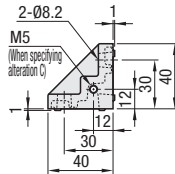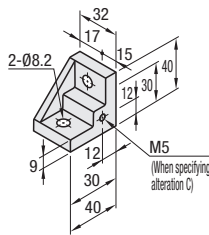

Material: ADC12



Example

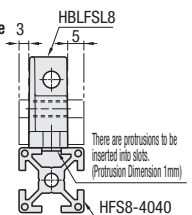

There are protrusions to be inserted into slots. (Protrusion Dimension 1mm)

HFS8-4040

Can be combined with both cover plates of 5mm and 3mm thickness.

Part Number	Mass (g)	Applicable Screw, T Nut		Allowable Load (N)	Unit Price (1-99 pc(s))	Volume Discount Rate (100~200)
		Screw	T Nut			
HBLFSL8	46	CBM8-20	2 HNTT8-8	2 2058		