


■ **Features:** Flathead screws for countersunk holes such as on hinges, etc.

■ **Phillips Truss Machine Screws**



Type	Material	Surface Treatment
HCBM	Carbon Steel for Mechanical Structure	Bright Chromate Plating
SHCBM	SUS304 Equivalent	-
HCBMB	Carbon Steel for Mechanical Structure	Trivalent Chromate (Black)

HCBM (Bright Chromate Plating)
 HCBMB (Trivalent Chromate, Black)
 SHCBM (Stainless Steel)

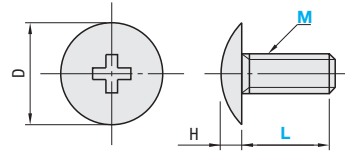

Part Number	Type	M	L	D	H	HCBM		SHCBM		HCBMB	
						Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
HCBM SHCBM	3 - 6	3	6	6.9	1.9						
HCBM SHCBM HCBMB	4 - 5 8 12	4	5 8 12	9.4	2.5						
HCBM SHCBM HCBMB	5 - 8 10 12 15 30 35	5	8 10 12 15 30 35	12	3.1						
HCBM SHCBM HCBMB	6 - 10 12 15	6	10 12 15	14	3.7						



Ordering Example Part Number
HCBM5-12

■ **Features:** Bulk packages of Hex Socket Flat Head Cap Screws and Phillips Truss Machine Screws. Bulk packages are cost effective for in-house stocks and large quantity use.

■ **Hex Socket Flat Head Cap Screws / Phillips Truss Machine Screws Small Screw Bulk Packages (500 pcs. per package)**




Type	Material	Surface Treatment
Hex Socket Flat Head Cap Screws	SCM435 SUS304 Equivalent	Trivalent Chromate -
Phillips Truss Machine Screws	Carbon Steel for Mechanical Structure SUS304 Equivalent	Trivalent Chromate (Black) Bright Chromate Plating
	Carbon Steel for Mechanical Structure	Trivalent Chromate (Black)

■ **Hex Socket Flat Head Cap Screws Bulk Packages**

HFBCM (Trivalent Chromate)
 SHFBS (Stainless Steel)
 HFBMB (Trivalent Chromate, Black)

■ **Phillips Truss Machine Screws Bulk Packages**

HCBM (Bright Chromate Plating)
 HCBMB (Trivalent Chromate, Black)
 SHCBM (Stainless Steel)

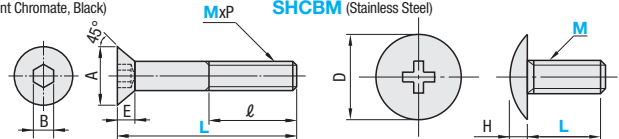

■ **Hex Socket Flat Head Cap Screws**

Type	Part Number			MxP	ℓ	A	E	B
	M	L	SET / (500 pcs. per pkg.)					
HFBCM SHFBS HFBMB	3	6 8 10 12	SET1	3x0.5	Full Thread	6	1.7	2
	4	6 8 10 12		4x0.7	Full Thread	8	2.3	2.5
	5	6 8 10 12 15 20		5x0.8	Full Thread	10	2.8	3
	6	8 10 12 15 20		6x1.0	Full Thread	12	3.3	4
	8	12 15 16 20		8x1.25	Full Thread	16	4.4	5
	10	16 18		10x1.5	Full Thread	20	5.5	6

■ **Phillips Truss Machine Screws**

Type	Part Number			D	H
	M	L	SET / (500 pcs. per pkg.)		
HCBM SHCBM HCBMB	3	6	SET1	6.9	1.9
	4	5 8 10 12		9.4	2.5
	5	8 10 12 15 30 35		12	3.1
	6	10 12 15		14	3.7



Ordering Example Part Number
HFBM5-10-SET1

M-L	HFBCM	SHFBS	HFBMB
	Unit Price of Set of 500 pcs. (SET1)	Unit Price of Set of 500 pcs. (SET1)	Unit Price of Set of 500 pcs. (SET1)
3-6			
8			
10			
12			
4-6			
8			
10			
12			
5-6			
8			
10			
12			
15			
20			
35			
40			
45			
6-8			
10			
12			
15			
20			
8-12			
15			
16			
20			
10-16			
18			

M-L	HCBM	SHCBM	HCBMB
	Unit Price of Set of 500 pcs. (SET1)	Unit Price of Set of 500 pcs. (SET1)	Unit Price of Set of 500 pcs. (SET1)
3-6			
4-5			
8			
10			
12			
5-8			
10			
12			
15			
30			
35			
6-10			
12			
15			