

RoHS10



Part Number	Material	Plate Thickness	Surface Treatment
PBLSS	SAPH	2.6mm	Trivalent Chromate

PBLSS1

PBLSS2


PBLSS3

PBLSS4

PBLSS5

PBLSS6


PBLSS7

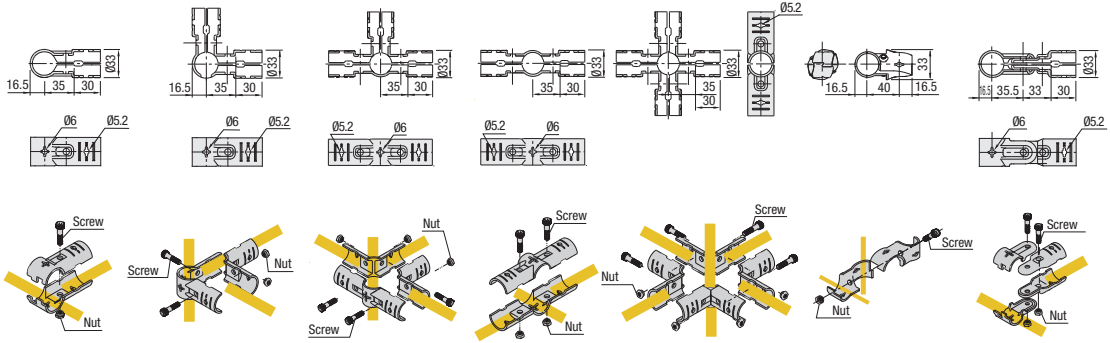

Part Number		Mass (g)	Included Screw		Unit Price
Type	No.		Size	Quantity	
PBLSS	1	160	M6-25	1	
	2	250		2	
	3	325		3	
	4	250		2	
	5	400		4	
	6	150		1	
	7	260		2	

■ Features of Joints for Stainless Steel Pipe Frame

The spurs that contact the pipe frames have been revised with improved geometry, and the retention force has been improved for use with stainless steel pipe frames. (For details: see P.889)

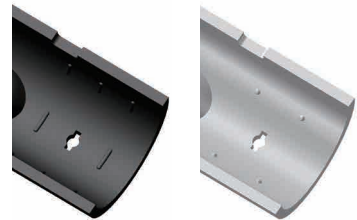

PBLSS1 (Conventional Type)

PBLSS1

⚠ Please note that the spurs may be crushed by repeated assembly/disassembly and may reduce the gripping force.




Ordering Example

Part Number  
PBLSS1

■ Inner Cap

JBS402S

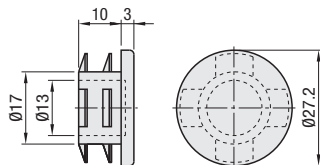

RoHS10

Material Polyethylene

Part Number	Mass (g)	Unit Price (4 pcs./pkg.)
JBS402S	3	

⚠ Contains 4 pcs./pkg. Check the order quantity before ordering.



Ordering Example

Part Number  
JBS402S