


Leveling Mounts - Space Saving

Foot (D dimension) is more compact than that of the conventional leveling mounts.



RoHS 10

Screw shafts turn.

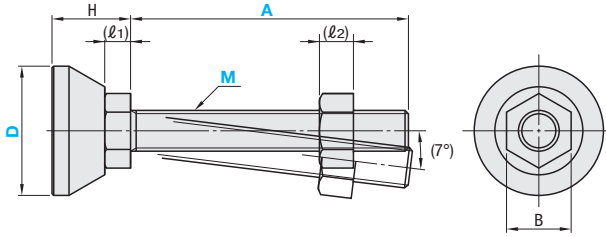

M Material: SS400 Equivalent
S Surface Treatment: Trivalent Chromate


Part Number Type	D	M (Coarse)	A			H	l ₁	l ₂	B	Allowable Vertical Load (kN)	Mass (g)	Unit Price
			20	50	100							
HNFJN	28	8	20	50	100	17.7	5.2	6.5	13	6.5	48	
	38	12	30	80	100	23	7.4	10	19	13	55	
	48	8	20	50	100	20.7	5.2	6.5	13	6.5	77	
		12	30	80	100	23	7.4	10	19	13	90	
	58	8	20	50	100	20.7	5.2	6.5	13	6.5	121	
		12	30	80	100	23	7.4	10	19	13	133	

Pivot Type



RoHS 10

Screw shafts turn.

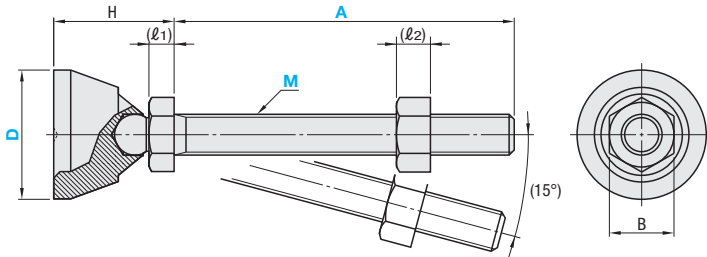

M Material: SS400 Equivalent
S Surface Treatment: Trivalent Chromate

Part Number Type	D	M (Coarse)	A			H	l ₁	l ₂	B	Allowable Vertical Load (kN)	Mass (g)	Unit Price
			20	50	100							
HNFJR	28	8	20	50	100	28.2	5.2	6.5	13	6.5	50	
	38	12	30	80	100	35.4	7.4	10	19	13	59	
	48	8	20	50	100	33.2	5.2	6.5	13	6.5	73	
		12	30	80	100	35.4	7.4	10	19	13	85	
	58	8	20	50	100	33.2	5.2	6.5	13	6.5	115	
		12	30	80	100	35.4	7.4	10	19	13	129	



Ordering Example

Part Number - M - A
HNFJR48 - 12 - 80