


Ball Valves

PT Male / PT Female, PT / PF Female

PT Male / PT Female



Type	Material	Max. Operating Pressure
BSRC	Main Body: SCS14A Ball Seat: Fluororesin	Water, Oil, Air, Gas: 4.12MPa Saturated Steam: 1MPa

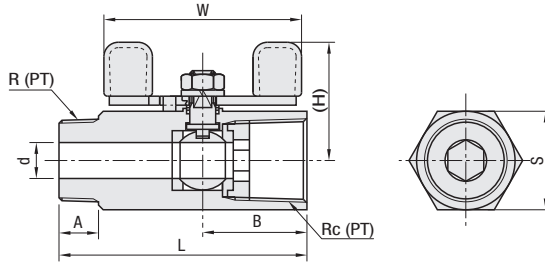

Part Number		R · Rc (PT)	d	A	B	S	L	(H)	W	Unit Price	Volume Discount Rate
Type	No.									1 ~ 4 pc(s).	5 ~ 10 pcs.
BSRC	8A	1/4	5	11	20	17	57	26	51		
	10A	3/8	7	12	28	21	68	29	55		

PT / PF Female




Type	Material	Max. Operating Pressure
BSGF	Main Body: SCS14A Ball Sheet: Fluororesin	Water, Oil, Air, Gas: 4.12MPa Saturated Steam: 1MPa

Application
With Rc (PT) male inlet port and G (PF) male outlet port, it is best suitable for use with a pressure gauge.

A (Lever Type)

B (Wing Knob Type)

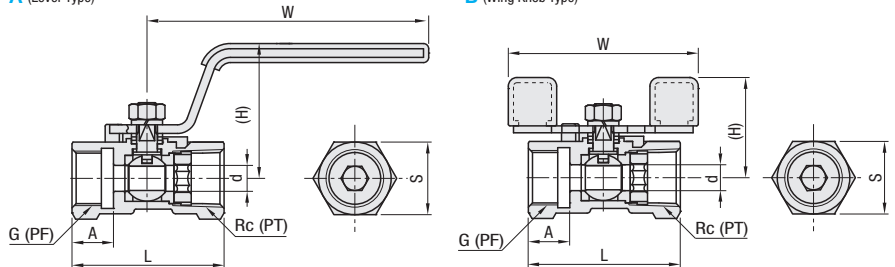

Part Number		Rc (PT)	G (PF)	L	A	d	S	Shape A		Shape B		Unit Price	Volume Discount Rate	
Type	No.							(H)	W	(H)	W			1 ~ 4 pc(s).
BSGF	A (Lever Type)	8A	1/4	1/4	39	11.5	5	17	27	65	27	51		
	B (Wing Knob Type)	10A	3/8	3/8	44	12	7	21	39	68	29	55		



Ordering Example

Part Number

BSRC8A
BSGFB8A