


Fluororesin Couplings / Fluororesin Valves

- Male Connectors
- Bore-Through Connectors

FENL (Male Connectors)
FECT (Bore-Through Connectors *Through Fitting)

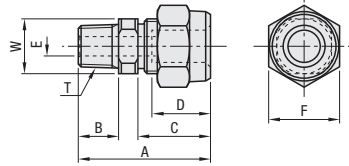


RoHS 10

Part Number		Nominal	T R(PT)	A	B	C	D	E	F	W	FENL		FECT	
Type	Applicable Tube O.D. (mm)										Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
FENL	4	1	1/8	26	9	11	7	3	10	10	1-4 pc(s)	5-20	1-4 pc(s)	5-20
		2	1/4	30	13					14				
	6	1	1/8	29	9					10				
		2	1/4	33	13	14	10	4	12	14				
FECT	8	1	1/8	33	9			4	14					
		2	1/4	36	13	18	12	6	17	14				
	10	3	3/8	37					6	17				
		4	1/2	43	17	21	16	8	22	17				

FECT has I.D. penetrated. Tube can be set at any desired portion by passing it through the body.
Size 8-1 is applicable only for FENL.

- Male Elbows

FEMLT

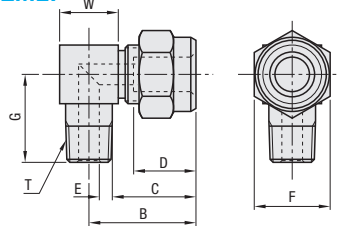


RoHS 10

Part Number		Nominal	T R(PT)	B	C	D	E	F	G	W	Unit Price	Volume Discount Rate
Type	Applicable Tube O.D. (mm)										1-4 pc(s)	5-20
FEMLT	4	1	1/8	17		11	7	3	10	16	11	
		2	1/4	18					20	14		
	6	1	1/8	20					17	11		
		2	1/4	21	14	10	4	12	21	14		
8	1	1/8	25					4	20	14		
		2	1/4	25	18	12	6	17	24	14		
	3	3/8	27					6	25	17		
		4	1/2	30	21	16	8	22	27	17		

- Unions

FETP

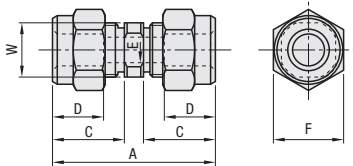


RoHS 10

Part Number		Applicable Tube O.D. (mm)	A	C	D	E	F	W	Unit Price	Volume Discount Rate
Type	1-4 pc(s)								5-20	
FETP	4	27	11	7	3	10	8			
	6	33	14	10	4	12	10			
	8	42	18	12	6	17	14			
	10	48	21	16	8	22	17			

- Union Elbows

FEUE

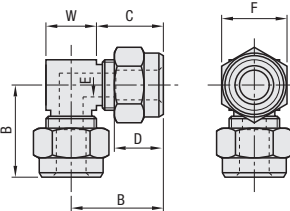


RoHS 10

Part Number		Applicable Tube O.D. (mm)	B	C	D	E	F	W	Unit Price	Volume Discount Rate
Type	1-4 pc(s)								5-20	
FEUE	4	15	11	7	3	10	8			
	6	19	14	10	4	12	10			
	8	25	18	12	6	17	14			
	10	30	21	16	8	22	17			

- Union Tees

FEUT

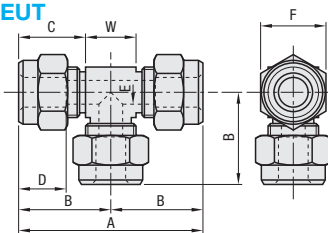


RoHS 10

Part Number		Applicable Tube O.D. (mm)	A	B	C	D	E	F	W	Unit Price	Volume Discount Rate
Type	1-4 pc(s)									5-20	
FEUT	4	30	15	11	7	3	10	8			
	6	38	19	14	10	4	12	10			
	8	50	25	18	12	6	17	14			
	10	60	30	21	16	8	22	17			

- Stepped Unions

FEUR

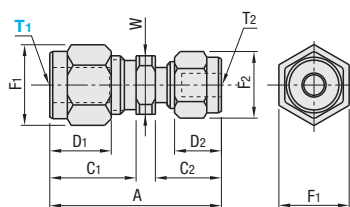

RoHS 10

Part Number		Applicable Tube O.D. (mm)	T2	A	C1	C2	D1	D2	W	F1	F2	Unit Price	Volume Discount Rate
Type	T1											1-4 pc(s)	5-20
FEUR	6	4	31	14	11	10	7	10	12	10			
	8	6	37	18	14	12	10	14	17	12			
	10	8	45	21	18	16	12	17	22	17			
	12	10	53	25	21	18	16	19	26	22			